


Hexagon head bolt DIN 931 Steel Plain 8.8 M4X25

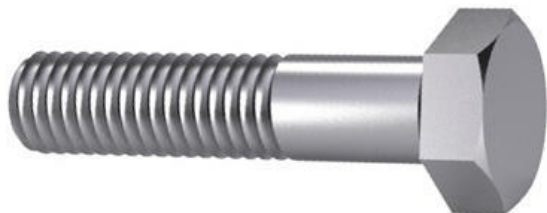

Article No.	01000.040.025
Brand	-
UBB	950351001066
UNSPSC	31161620
EAN	8715492006806
PKG. of 500	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M4
Length (L) (mm)	25

Standards

DIN	931
NF	E25-112
ASME	B18.2.3.1M
ISO	4014

Technical Specification

b (min.): L≤125mm	14
k	2.8
P	0.70
s	7

Technical Drawing

