


Hexagon head bolt DIN 931 Steel Plain 8.8 M4X40

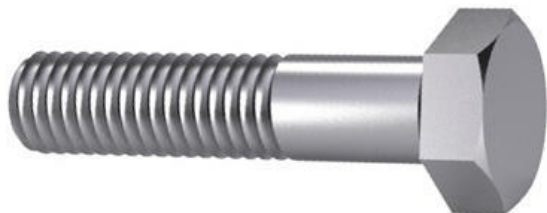

Article No.	01000.040.040
Brand	-
UBB	950351001223
UNSPSC	31161620
EAN	8715492006844
PKG. of 500	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M4
Length (L) (mm)	40

Standards

ISO	4014
NF	E25-112
ASME	B18.2.3.1M
DIN	931

Technical Specification

b (min.): L≤125mm	14
k	2.8
P	0.70
s	7

Technical Drawing

