


Hexagon head bolt DIN 931 Steel Plain 8.8 DIN 931 M10X120

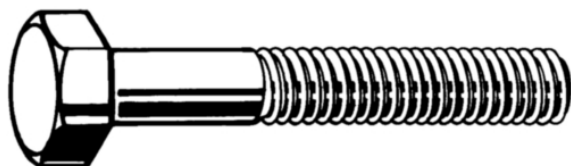

Article No.	01000.100.120
Brand	-
UBB	950351006685
UNSPSC	31161620
EAN	8715492007759
PKG. of 50	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Extra info	DIN 931
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width	17
Diameter (d-D)	M10
Length (L) (mm)	120

Standards

NEN	1555
DIN	931
ISO	4014
NF	E25-112
ASME	B18.2.3.1M

Technical Specification

b (min.): 125mm<L≤200mm	32
k	6.4
s	17
b (min.): L>200mm	45
b (min.): L≤125mm	26
P	1.50

Technical Drawing

