


## Hexagon head bolt DIN 931 Steel Plain 8.8 M14X150

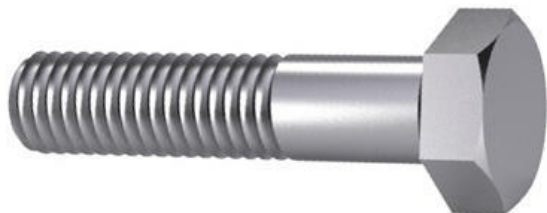

Article No.	01000.140.150
Brand	-
UBB	950351010968
UNSPSC	31161620
EAN	8715492008381
PKG. of 25	Full Box Only

### Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Wrench width (s) (mm)	22
Diameter (d-D)	M14
Length (L) (mm)	150

### Standards

ASME	B18.2.3.1M
DIN	931
NF	E25-112
ISO	4014

### Technical Specification

b (min.): 125mm<L≤200mm	40
b (min.): L>200mm	53
b (min.): L≤125mm	34
k	8.8
P	2
s	22

### Technical Drawing

