


Hexagon head bolt DIN 931 Steel Plain 8.8 M20X85

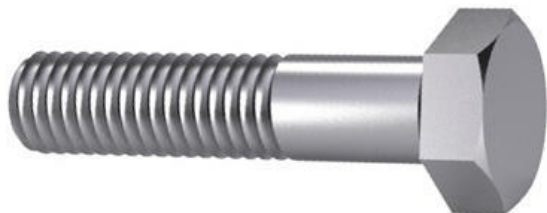

Article No.	01000.200.085
Brand	-
UBB	952351146594
UNSPSC	31161620
EAN	8715492009197
PKG. of 25	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M20
Length (L) (mm)	85

Standards

ASME	B18.2.3.1M
NF	E25-112
ISO	4014
DIN	931

Technical Specification

b (min.): 125mm $L \leq 200\text{mm}$	52
b (min.): $L > 200\text{mm}$	65
b (min.): $L \leq 125\text{mm}$	46
k	12.5
P	2.50
s	30

Technical Drawing

