


Hexagon head bolt DIN 931 Steel Plain 8.8 DIN 931 M20X170

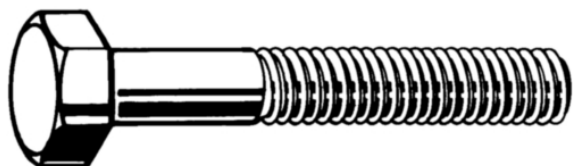

Article No.	01000.200.170
Brand	-
UBB	950351914441
UNSPSC	31161620
EAN	8715492009302
PKG. of 10	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Extra info	DIN 931
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M20
Length (L) (mm)	170

Standards

NEN	1555
NF	E25-112
ASME	B18.2.3.1M
DIN	931
ISO	4014

Technical Specification

P	2.50
b (min.): L>200mm	65
b (min.): L≤125mm	46
s	30
b (min.): 125mm<L≤200mm	52
k	12.5

Technical Drawing

