


Hexagon head bolt DIN 931 Steel Plain 8.8 M42X180

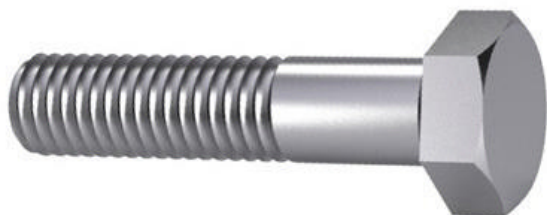

Article No.	01000.420.180
Brand	-
UBB	950351032822
UNSPSC	31161620
EAN	8715492011664
PKG. of 1	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M42
Length (L) (mm)	180

Standards

ASME	B18.2.3.1M
NF	E25-112
DIN	931
ISO	4014

Technical Specification

b (min.): 125mm $L \leq 200\text{mm}$	96
b (min.): $L > 200\text{mm}$	109
b (min.): $L \leq 125\text{mm}$	90
k	26
P	4.50
s	65

Technical Drawing

