


Hexagon head bolt DIN 931 Steel Plain 8.8 M48X140

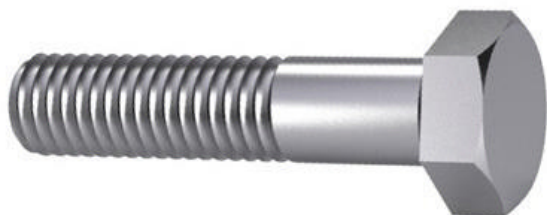

Article No.	01000.480.140
Brand	-
UBB	950351034984
UNSPSC	31161620
EAN	8715492012081
PKG. of 1	Full Box Only

Technical Parameters

Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Diameter (d-D)	M48
Length (L) (mm)	140

Standards

DIN	931
ASME	B18.2.3.1M
ISO	4014
NF	E25-112

Technical Specification

b (min.): 125mm $L \leq 200\text{mm}$	108
b (min.): $L > 200\text{mm}$	121
b (min.): $L \leq 125\text{mm}$	102
k	30
P	5
s	75

Technical Drawing

