


## Hexagon head bolt DIN 931 Steel Plain 8.8 M52X320

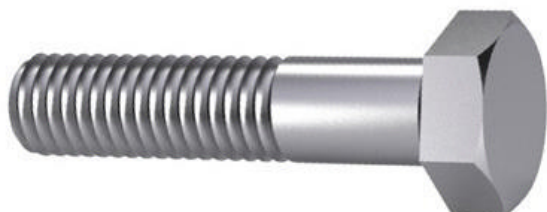

|             |               |
|-------------|---------------|
| Article No. | 01000.520.320 |
| Brand       | -             |
| UBB         | 950351036476  |
| UNSPSC      | 31161620      |
| EAN         | 8715492012395 |
| PKG. of 1   | Full Box Only |

### Technical Parameters

|                   |               |
|-------------------|---------------|
| Class             | 8.8           |
| Driving features  | Hexagon       |
| Head shape        | Hexagon head  |
| Material          | Steel         |
| Thread direction  | Right         |
| Surface treatment | Plain         |
| Thread            | Metric thread |
| Diameter (d-D)    | M52           |
| Length (L) (mm)   | 320           |

### Standards

|      |            |
|------|------------|
| ASME | B18.2.3.1M |
| ISO  | 4014       |
| DIN  | 931        |
| NF   | E25-112    |

### Technical Specification

|   |     |
|---|-----|
| b (min.):<br>125mm <math>L \leq 200\text{mm}</math> | 116 |
| b (min.): $L > 200\text{mm}$                        | 119 |
| k   | 33  |
| P   | 5   |
| s   | 80  |

### Technical Drawing

