


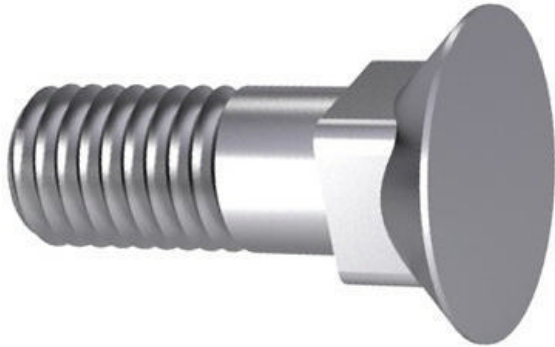

DIN 608 Plough Bolt with Flat Countersunk Head and Square Neck, Plain, Class 8.8 M10X60

Article number	01036.100.060
Brand	-
UBB	951351989276
UNSPSC	31161612
EAN	8715492017840
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M10
Length	60 mm
Class	8.8
Head shape	Countersunk head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Standards

DIN	≈608
-----	------

Technical Specification

b (min.)	26
d-D	M10
dk (max.)	19.65
L (mm)	60
P	1.5
fn (max.)	8.45
v (max.)	10.58

Technical Drawing

