


## Hexagon head bolt ISO 4014 Steel Zinc plated 8.8 M6X60

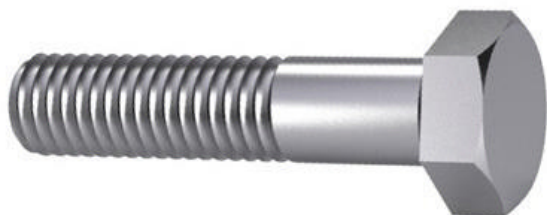

Article number 01200.060.060

Brand -

UBB 950351142142

UNSPSC 31161620

EAN 8715492024947

PKG. of 200 Full Box Only

### Technical Parameters

Diameter (d-D)	M6
Length (L) (mm)	60
Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

### Standards

DIN	931
NF	E25-112
ASME	B18.2.3.1M
ISO	4014

### Technical Specification

b (min.): 125mm <math>L \leq 200\text{mm}</math>	24
b (min.): $L \leq 125\text{mm}$	18
k	4
P	1
s	10

### Technical Drawing

