


Hexagon head bolt ISO 4014 Steel Zinc plated 8.8 M10X75

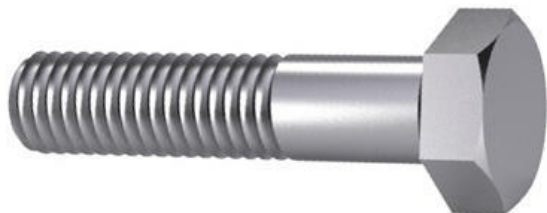

Article number	01200.100.076
Brand	-
UBB	952351613460
UNSPSC	31161620
EAN	8715492025586
PKG. of 100	Full Box Only

Technical Parameters

Diameter (d-D)	M10
Length (L) (mm)	75
Class	8.8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread
Wrench width (s) (mm)	16

Standards

NF	E25-112
DIN	931
ISO	4014
ASME	B18.2.3.1M

Technical Specification

b (min.): 125mm $L \leq 200\text{mm}$	32
b (min.): $L > 200\text{mm}$	45
b (min.): $L \leq 125\text{mm}$	26
k	6.4
P	1.50
s	16

Technical Drawing

