


Structural assembly set EN 15048 Steel Zinc plated 8.8/8 M27X150

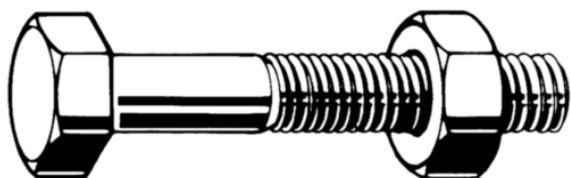

Article number 01222.270.150

Brand -

UBB 500613350353

UNSPSC 31161620

EAN 8715494441971

PKG. of 1 Full Box Only

Technical Parameters

Diameter (d-D) M27

Length (L) (mm) 150

Info

Full boxes only. European constructions must comply with the Construction Products Regulation (CPR) in order to ensure the safety of persons and objects. Generally, construction products according to harmonized European standards (hEN standards) should be used for this purpose. Bolting assemblies for non-preloaded structural bolting according to EN 15048-1 are compliant with the CPR. The manufacturer of the assemblies is CE certified for their production. Bolts and nuts are packaged together in single sealed boxes.

Standards

EN 15048

ISO 4014/4032

	A Declaration of Performance (DoP) is available.
Class	8.8/8
Driving features	Hexagon
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Technical Specification

b (min.): 125mm $L \leq 200\text{mm}$	66
b (min.): $L > 200\text{mm}$	79
b (min.): $L \leq 125\text{mm}$	60
k	17
m (max.)	23.8
P	3
s	41

Technical Drawing

