


Hexagon head bolt DIN 931 Steel Plain 12.9 DIN 931 M8X40

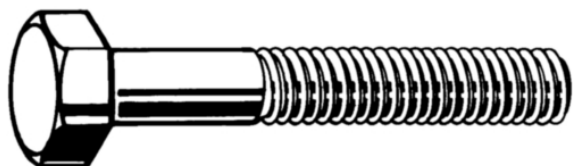

Article No.	04108.080.040
Brand	-
UBB	955351407767
UNSPSC	31161620
EAN	8715493849570
PKG. of 200	Full Box Only

Technical Parameters

Diameter (d-D)	M8
Length (L) (mm)	40
Class	12.9
Driving features	Hexagon
Extra info	DIN 931
Head shape	Hexagon head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Info	Warning: electroplating of these products may cause hydrogen embrittlement.

Standards

DIN	931
ISO	4014
ISO	4014

Technical Specification

b (min.): 125mm $L \leq 200\text{mm}$	28
b (min.): $L \leq 125\text{mm}$	22
k	5.3
P	1.25
s	13

Technical Drawing

