


## Hexagon socket countersunk head screw ISO 10642 Steel Plain 010.9 M16X60

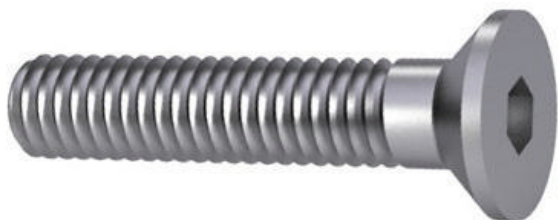

Article number	07400.160.060
----------------	---------------

Brand	-
-------	---

UBB	950351482530
-----	--------------

UNSPSC	31161518
--------	----------

EAN	8715492084002
-----	---------------

PKG. of 50	Full Box Only
------------	---------------

### Technical Parameters

Diameter (d-D)	M16
----------------	-----

Length (L) (mm)	60
-----------------	----

Info	All thread lengths are guide values only and may deviate. Due to the unfavourable head geometry these fasteners have reduced loadability. Steel fasteners with reduced loadability are marked with a '0' preceding the property class mark, e.g. '010.9'. Stainless steel fasteners with reduced loadability are either marked with a '0' preceding the property class mark, e.g. 'A2-070', or with the steel grade only, e.g. 'A2'.
------	--

Class	010.9
-------	-------

Driving features	Hexagon socket
------------------	----------------

Head shape	Countersunk head
------------	------------------

Material	Steel
----------	-------

### Standards

DIN	≈7991
-----	-------

ISO	10642
-----	-------

Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Info	Warning: electroplating of these products may cause hydrogen embrittlement.

### Technical Specification

b (min.)	48
$d_k$ (max.)	30.61
Full thread if $L \leq$	70
k (max.)	8.8
P	2
s	10
$\alpha$	$90^\circ$

### Technical Drawing

