


Hexagon socket countersunk head screw ISO 10642 Steel Zinc plated 08.8 M4X16

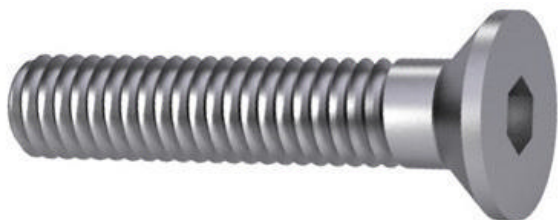

Article number	07470.040.016
----------------	---------------

Brand	-
-------	---

UBB	950351486671
-----	--------------

UNSPSC	31161518
--------	----------

EAN	8715492151131
-----	---------------

PKG. of 200	Full Box Only
-------------	---------------

Technical Parameters

Diameter (d-D)	M4
----------------	----

Length (L) (mm)	16
-----------------	----

Info	All thread lengths are guide values only and may deviate. Due to the unfavourable head geometry these fasteners have reduced loadability. Steel fasteners with reduced loadability are marked with a '0' preceding the property class mark, e.g. '010.9'. Stainless steel fasteners with reduced loadability are either marked with a '0' preceding the property class mark, e.g. 'A2-070', or with the steel grade only, e.g. 'A2'.
------	--

Class	08.8
-------	------

Driving features	Hexagon socket
------------------	----------------

Head shape	Countersunk head
------------	------------------

Material	Steel
----------	-------

Standards

ISO	10642
-----	-------

DIN	≈7991
-----	-------

Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Technical Specification

b (min.)	20
d_k (max.)	7.96
Full thread if $L \leq$	25
k (max.)	2.48
P	0.70
s	2.5
α	90°

Technical Drawing

