



Hexagon socket set screw with dog point DIN 915 Steel Plain 45H M3X3

Article number	07820.030.003
Brand	-
UBB	951351205822
UNSPSC	31161518
EAN	8715492160782
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M3
Length	3 mm
Class	45H
Driving features	Hexagon socket
Material	Steel
Thread direction	Right
Point	Dog
Surface treatment	Plain
Thread	Metric thread

Info

These set screws are designed for pressure loads and are not suitable for tensile- or shear loads.


Standards

NF	E27-182
ISO	4028
BS	4168-4
DIN	915
ASME	B18.3.6M
NEN	2344

Technical Specification

d-D	M3
dp (max.)	2
L (mm)	3
P	0.5
s	1.5
t (min.)	1.2
z long (min.)	1.5
z long if L ≥	6

Technical Drawing

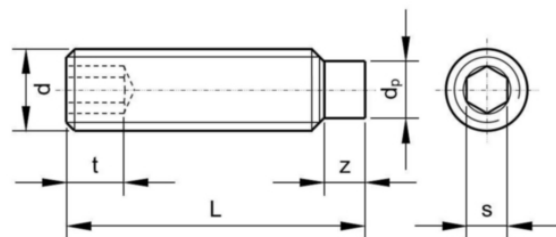

z short (min.) 0.75

FABORY