


Hexagon head bolt with hexagon nut DIN 601/555 Steel Plain 4.6 M12X260

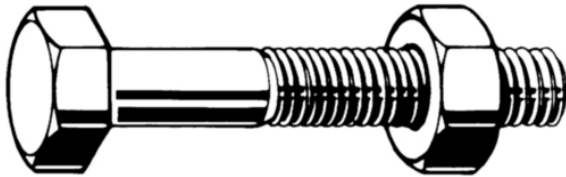

Article number	08000.120.260
Brand	-
UBB	500648014628
UNSPSC	31161620
EAN	8717077272941
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M12
Length	260 mm
Class	4.6
Driving features	Hexagon
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread
Info	The property class of the corresponding nuts is 4 as a minimum.

Standards

NEN	102/697
DIN	601/555
ISO	≈4016/4033
NF	E25-115-1/E25-402

Technical Specification

b (min.): 125mmL≤200mm	36
b (min.): L200mm	49
b (min.): L≤125mm	30
d-D	M12
k	7.5
L (mm)	260
m	10
P	1.75
s	19

Technical Drawing

