


Flat countersunk nib bolt with hexagon nut DIN 604/555 Steel Plain 4.6 M6X40

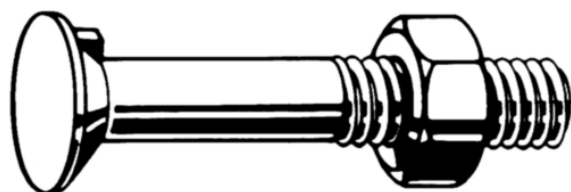

Article number	08070.060.040
Brand	-
UBB	500645150961
UNSPSC	31161612
EAN	8717077056008
PKG. of 200	Full Box Only

Technical Parameters

Diameter (d-D)	M6
Length (L) (mm)	40
Info	The property class of the corresponding nuts is 4 as a minimum.
Class	4.6
Head shape	Countersunk head
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Standards

DIN	604/555
-----	---------

Technical Specification

b (min.): 125mm<L≤200mm	24
b (min.): L≤125mm	18
d _k (max.)	12.55
g (max.)	2.5
k	4
m	5
P	1
s	10
α (min.)	90°

Technical Drawing

