


## DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M5X60

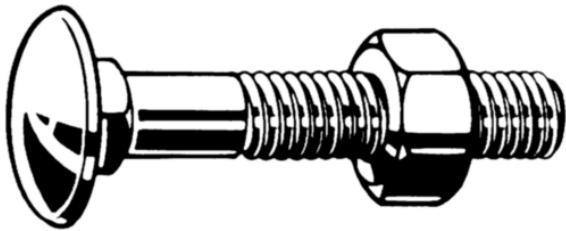

|                |               |
|----------------|---------------|
| Article number | 08250.050.060 |
| Brand          | -             |
| UBB            | 950351600354  |
| UNSPSC         | 31161612      |
| EAN            | 8715492554796 |
| PKG. of 200    | Full Box Only |

### Technical Parameters

|                   |               |
|-------------------|---------------|
| Diameter          | M5            |
| Length            | 60 mm         |
| Class             | 4.6           |
| Material          | Steel         |
| Thread direction  | Right         |
| Surface treatment | Zinc plated   |
| Thread            | Metric thread |

**Info**  
The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


### Standards

|     |                  |
|-----|------------------|
| ISO | ≈8677/4034       |
| BS  | ≈4933/3692       |
| DIN | 603/555          |
| NF  | ≈E27-351/E25-402 |
| NEN | ≈303/697         |

### Technical Specification

|                           |       |
|---------------------------|-------|
| b (min.):<br>125mmL≤200mm | 22    |
| b (min.): L≤125mm         | 16    |
| d-D                       | M5    |
| dk (max.)                 | 13.55 |
| k (max.)                  | 3.3   |
| L (mm)                    | 60    |
| m                         | 4     |
| P                         | 0.8   |
| fn (max.)                 | 4.1   |

### Technical Drawing

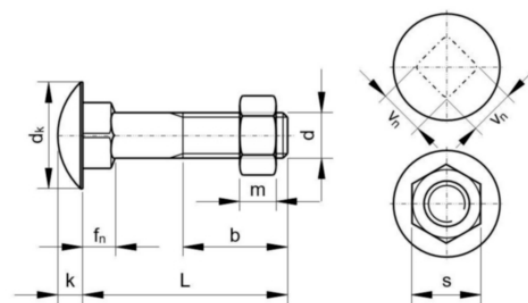

s

8

Vn (max.)

5.48

