


DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M5X80

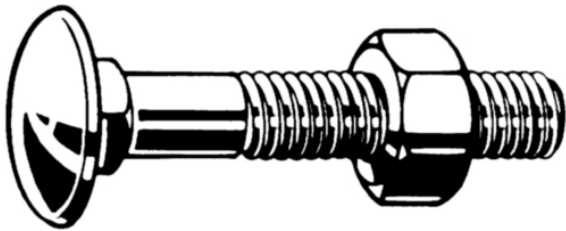

Article number	08250.050.080
Brand	-
UBB	952351692654
UNSPSC	31161612
EAN	8715492554826
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M5
Length	80 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

NF	≈E27-351/E25-402
DIN	603/555
BS	≈4933/3692
ISO	≈8677/4034
NEN	≈303/697

Technical Specification

b (min.): 125mmL≤200mm	22
b (min.): L≤125mm	16
d-D	M5
dk (max.)	13.55
k (max.)	3.3
L (mm)	80
m	4
P	0.8
fn (max.)	4.1

Technical Drawing

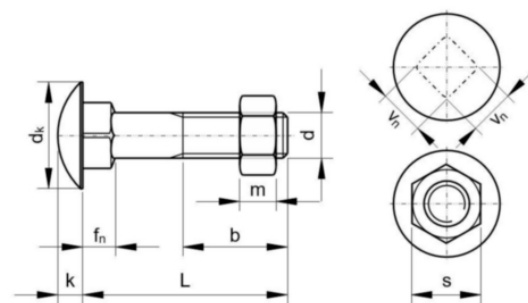

s

8

Vn (max.)

5.48

