


DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M6X35

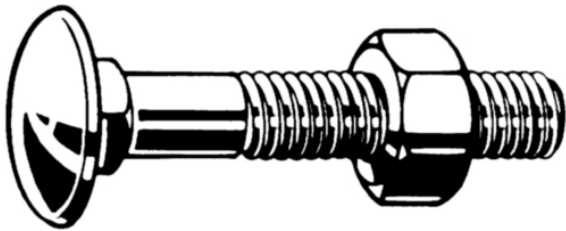

Article number	08250.060.035
Brand	-
UBB	950351601006
UNSPSC	31161612
EAN	8715492554888
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M6
Length	35 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

NF	≈E27-351/E25-402
ISO	≈8677/4034
NEN	≈303/697
DIN	603/555
BS	≈4933/3692

Technical Specification

b (min.): 125mmL≤200mm	24
b (min.): L≤125mm	18
d-D	M6
dk (max.)	16.55
k (max.)	3.88
L (mm)	35
m	5
P	1
fn (max.)	4.6

Technical Drawing

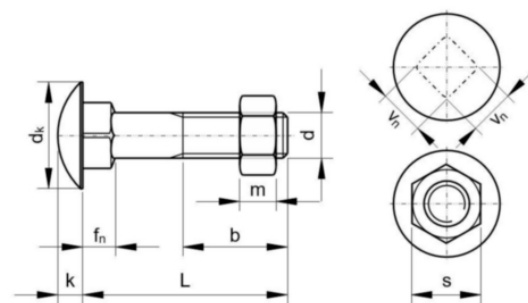

s

10

Vn (max.)

6.48

