


DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M6X45

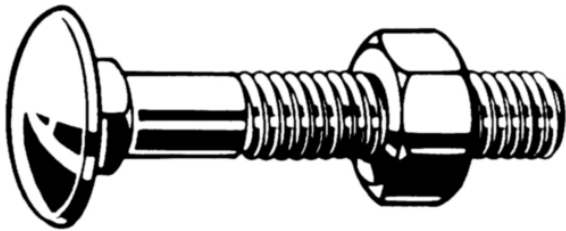

Article number	08250.060.045
Brand	-
UBB	950351601261
UNSPSC	31161612
EAN	8715492554901
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M6
Length	45 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

DIN	603/555
NEN	≈303/697
ISO	≈8677/4034
BS	≈4933/3692
NF	≈E27-351/E25-402

Technical Specification

b (min.): 125mmL≤200mm	24
b (min.): L≤125mm	18
d-D	M6
dk (max.)	16.55
k (max.)	3.88
L (mm)	45
m	5
P	1
fn (max.)	4.6

Technical Drawing

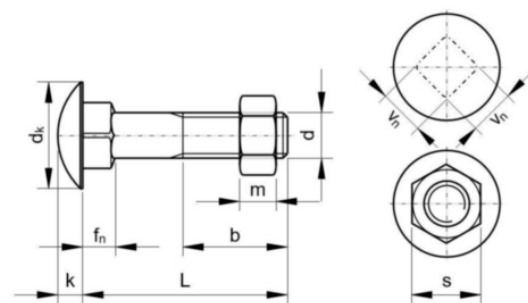

s

10

Vn (max.)

6.48

