


Carriage bolt with hexagon nut DIN 603/555 Steel Zinc plated 4.6 M6X90

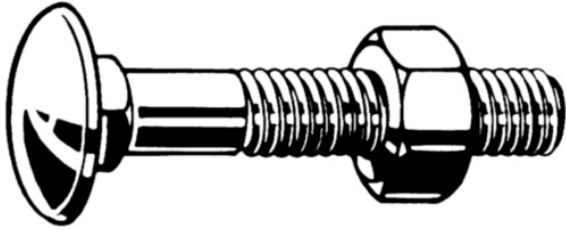

Article number	08250.060.090
Brand	-
UBB	950351602095
UNSPSC	31161612
EAN	8715492554987
PKG. of 100	Full Box Only

Technical Parameters

Diameter (d-D)	M6
Length (L) (mm)	90
Info	The property class of the corresponding nuts is 4 as a minimum.
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Standards

ISO	≈8677/4034
DIN	603/555
NF	≈E27-351 / E25-402
BS	≈4933/3692

Technical Specification

b (min.): 125mm<L≤200mm	24
b (min.): L≤125mm	18
d _k (max.)	16.55
k (max.)	3.88
m	5
P	1
f _n (max.)	4.6
s	10
V _n (max.)	6.48

Technical Drawing

