


## Carriage bolt with hexagon nut DIN 603/555 Steel Zinc plated 4.6 M6X140

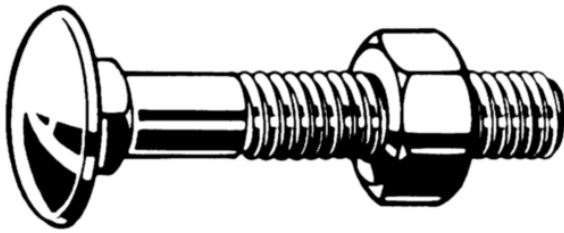

Article number	08250.060.140
Brand	-
UBB	950351602418
UNSPSC	31161612
EAN	8715492555038
PKG. of 100	Full Box Only

### Technical Parameters

Diameter (d-D)	M6
Length (L) (mm)	140
Info	The property class of the corresponding nuts is  4  as a minimum.
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

### Standards

BS	≈4933/3692
DIN	603/555
NF	≈E27-351 / E25-402
ISO	≈8677/4034

### Technical Specification

b (min.): 125mm<L≤200mm	24
b (min.): L≤125mm	18
d <sub>k</sub> (max.)	16.55
k (max.)	3.88
m	5
P	1
f <sub>n</sub> (max.)	4.6
s	10
V <sub>n</sub> (max.)	6.48

### Technical Drawing

