

DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M8X25

Article number	08250.080.025
Brand	-
UBB	950351602665
UNSPSC	31161612
EAN	8715492555205
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M8
Length	25 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

ISO	≈8677/4034
NF	≈E27-351/E25-402
DIN	603/555
NEN	≈303/697
BS	≈4933/3692

Technical Specification

b (min.): 125mmL≤200mm	28
b (min.): L200mm	41
b (min.): L≤125mm	22
d-D	M8
dk (max.)	20.65
k (max.)	4.88
L (mm)	25
m	6.5
P	1.25

Technical Drawing

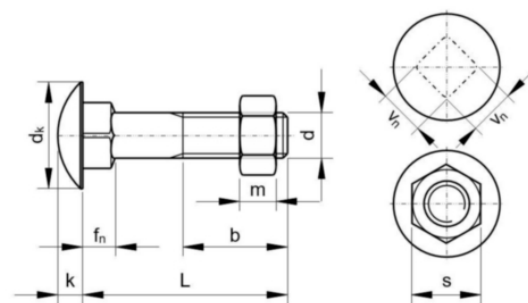

fn (max.)	5.6
-----------	-----

s	13
---	----

Vn (max.)	8.58
-----------	------