

DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M8X30

Article number	08250.080.030
Brand	-
UBB	950351602749
UNSPSC	31161612
EAN	8715492555212
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M8
Length	30 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

ISO	≈8677/4034
DIN	603/555
NF	≈E27-351/E25-402
NEN	≈303/697
BS	≈4933/3692

Technical Specification

b (min.): 125mmL≤200mm	28
b (min.): L200mm	41
b (min.): L≤125mm	22
d-D	M8
dk (max.)	20.65
k (max.)	4.88
L (mm)	30
m	6.5
P	1.25

Technical Drawing

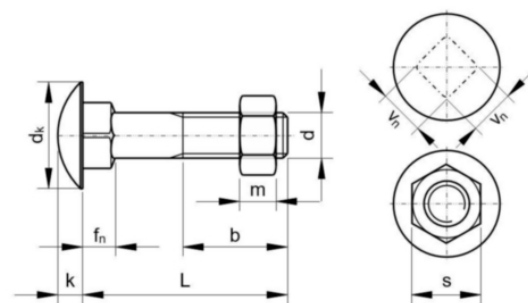

fn (max.) 5.6

s 13

Vn (max.) 8.58