


DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M8X40

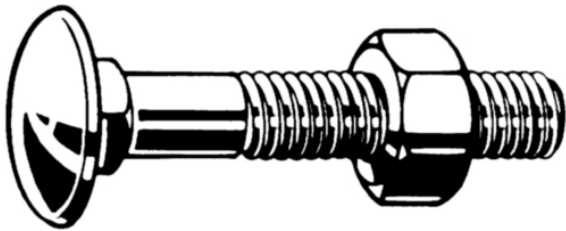

Article number	08250.080.040
Brand	-
UBB	950351602905
UNSPSC	31161612
EAN	8715492555236
PKG. of 200	Full Box Only

Technical Parameters

Diameter	M8
Length	40 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

NF	≈E27-351/E25-402
ISO	≈8677/4034
BS	≈4933/3692
NEN	≈303/697
DIN	603/555

Technical Specification

b (min.): 125mmL≤200mm	28
b (min.): L200mm	41
b (min.): L≤125mm	22
d-D	M8
dk (max.)	20.65
k (max.)	4.88
L (mm)	40
m	6.5
P	1.25

Technical Drawing

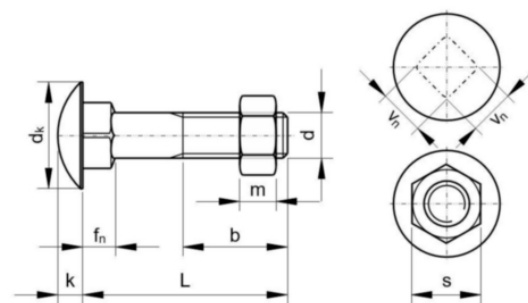

fn (max.) 5.6

s 13

Vn (max.) 8.58