

DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M8X130

Article number	08250.080.130
Brand	-
UBB	950351604232
UNSPSC	31161612
EAN	8715492555366
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M8
Length	130 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info	The property class of the corresponding nuts is 4 as a minimum. Depending the supplier material class can differ (4.6 or 4.8)
------	---


Standards

BS	≈4933/3692
NF	≈E27-351/E25-402
DIN	603/555
ISO	≈8677/4034
NEN	≈303/697

Technical Specification

b (min.): 125mmL≤200mm	28
b (min.): L200mm	41
b (min.): L≤125mm	22
d-D	M8
dk (max.)	20.65
k (max.)	4.88
L (mm)	130
m	6.5
P	1.25

Technical Drawing

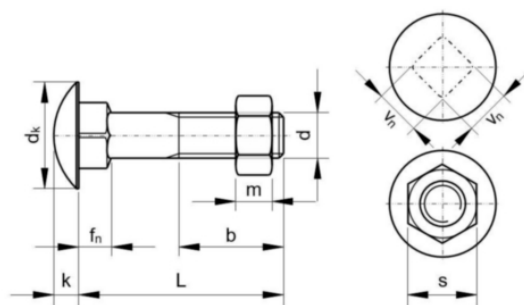

fn (max.) 5.6

s 13

Vn (max.) 8.58