


DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M8X180

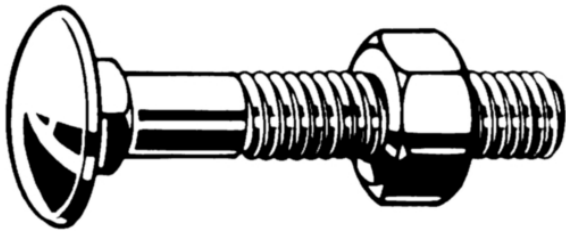

Article number	08250.080.180
Brand	-
UBB	950351604646
UNSPSC	31161612
EAN	8715492555410
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M8
Length	180 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

DIN	603/555
ISO	≈8677/4034
NEN	≈303/697
NF	≈E27-351/E25-402
BS	≈4933/3692

Technical Specification

b (min.): 125mmL≤200mm	28
b (min.): L200mm	41
b (min.): L≤125mm	22
d-D	M8
dk (max.)	20.65
k (max.)	4.88
L (mm)	180
m	6.5
P	1.25

Technical Drawing

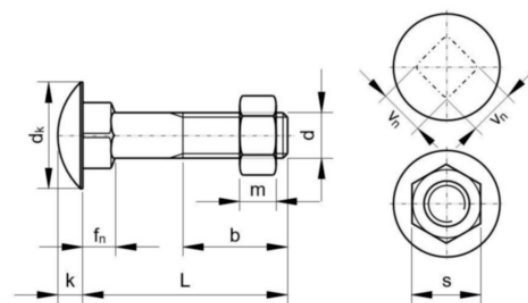

fn (max.) 5.6

s 13

Vn (max.) 8.58