


Carriage bolt with hexagon nut DIN 603/555 Steel Zinc plated 4.6 M10X35

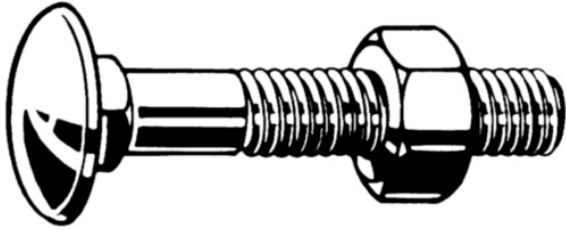

| | |
|----------------|---------------|
| Article number | 08250.100.035 |
| Brand | - |
| UBB | 950351605148 |
| UNSPSC | 31161612 |
| EAN | 8715492555465 |
| PKG. of 100 | Full Box Only |

Technical Parameters

| | |
|-------------------|---|
| Diameter (d-D) | M10 |
| Length (L) (mm) | 35 |
| Info | The property class of the corresponding nuts is 4 as a minimum. |
| Class | 4.6 |
| Material | Steel |
| Thread direction | Right |
| Surface treatment | Zinc plated |
| Thread | Metric thread |

Standards

| | |
|-----|--------------------|
| NF | ≈E27-351 / E25-402 |
| DIN | 603/555 |
| BS | ≈4933/3692 |
| ISO | ≈8677/4034 |

Technical Specification

| | |
|---|-------|
| b (min.): 125mm $L \leq 200\text{mm}$ | 32 |
| b (min.): $L > 200\text{mm}$ | 45 |
| b (min.): $L \leq 125\text{mm}$ | 26 |
| d_k (max.) | 24.65 |
| k (max.) | 5.38 |
| m | 8 |
| P | 1.50 |
| f_n (max.) | 6.6 |
| s | 17 |
| V_n (max.) | 10.58 |

Technical Drawing

