

DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M10X60

Article number	08250.100.060
Brand	-
UBB	950351605635
UNSPSC	31161612
EAN	8715492555519
PKG. of 100	Full Box Only

Technical Parameters

Diameter	M10
Length	60 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

NF	≈E27-351/E25-402
BS	≈4933/3692
NEN	≈303/697
DIN	603/555
ISO	≈8677/4034

Technical Specification

b (min.): 125mmL≤200mm	32
b (min.): L200mm	45
b (min.): L≤125mm	26
d-D	M10
dk (max.)	24.65
k (max.)	5.38
L (mm)	60
m	8
P	1.5

Technical Drawing

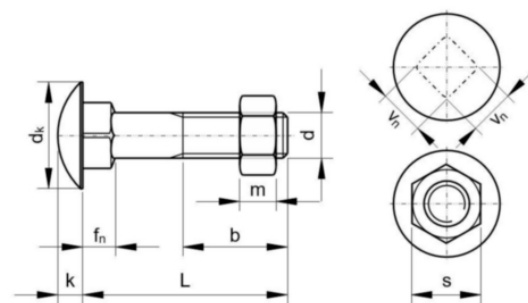

fn (max.) 6.6

s 17

Vn (max.) 10.58