

DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M10X120

Article number	08250.100.120
Brand	-
UBB	950351606476
UNSPSC	31161612
EAN	8715492555595
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M10
Length	120 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info
The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

BS	≈4933/3692
DIN	603/555
ISO	≈8677/4034
NF	≈E27-351/E25-402
NEN	≈303/697

Technical Specification

b (min.): 125mmL≤200mm	32
b (min.): L200mm	45
b (min.): L≤125mm	26
d-D	M10
dk (max.)	24.65
k (max.)	5.38
L (mm)	120
m	8
P	1.5

Technical Drawing

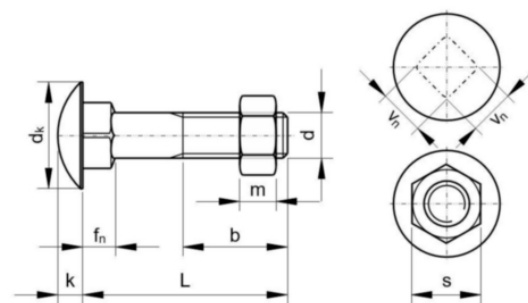

fn (max.) 6.6

s 17

Vn (max.) 10.58