

DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M12X110

Article number	08250.120.110
Brand	-
UBB	950351609447
UNSPSC	31161612
EAN	8715492555946
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M12
Length	110 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

BS	≈4933/3692
ISO	≈8677/4034
NF	≈E27-351/E25-402
DIN	603/555
NEN	≈303/697

Technical Specification

b (min.): 125mmL≤200mm	36
b (min.): L200mm	49
b (min.): L≤125mm	30
d-D	M12
dk (max.)	30.65
k (max.)	6.95
L (mm)	110
m	10
P	1.75

Technical Drawing

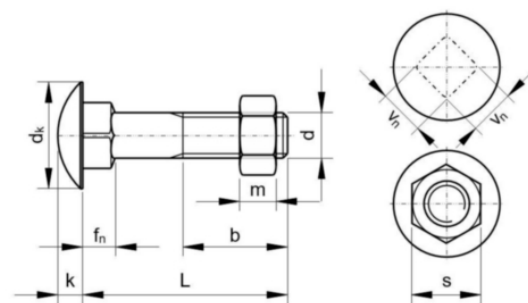

fn (max.) 8.75

s 19

Vn (max.) 12.7