

DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M12X140

Article number	08250.120.140
Brand	-
UBB	950351609777
UNSPSC	31161612
EAN	8715492555977
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M12
Length	140 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

NEN	≈303/697
DIN	603/555
BS	≈4933/3692
NF	≈E27-351/E25-402
ISO	≈8677/4034

Technical Specification

b (min.): 125mmL≤200mm	36
b (min.): L200mm	49
b (min.): L≤125mm	30
d-D	M12
dk (max.)	30.65
k (max.)	6.95
L (mm)	140
m	10
P	1.75

Technical Drawing

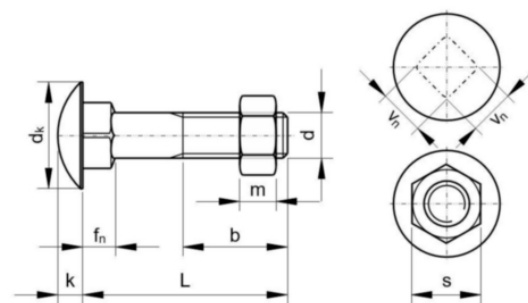

fn (max.) 8.75

s 19

Vn (max.) 12.7