

## DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M12X190

|                |               |
|----------------|---------------|
| Article number | 08250.120.190 |
| Brand          | -             |
| UBB            | 950351610254  |
| UNSPSC         | 31161612      |
| EAN            | 8715492556028 |
| PKG. of 25     | Full Box Only |

### Technical Parameters

|                   |               |
|-------------------|---------------|
| Diameter          | M12           |
| Length            | 190 mm        |
| Class             | 4.6           |
| Material          | Steel         |
| Thread direction  | Right         |
| Surface treatment | Zinc plated   |
| Thread            | Metric thread |

**Info**

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


### Standards

|     |                  |
|-----|------------------|
| BS  | ≈4933/3692       |
| ISO | ≈8677/4034       |
| NF  | ≈E27-351/E25-402 |
| DIN | 603/555          |
| NEN | ≈303/697         |

### Technical Specification

|                           |       |
|---------------------------|-------|
| b (min.):<br>125mmL≤200mm | 36    |
| b (min.): L200mm          | 49    |
| b (min.): L≤125mm         | 30    |
| d-D                       | M12   |
| dk (max.)                 | 30.65 |
| k (max.)                  | 6.95  |
| L (mm)                    | 190   |
| m                         | 10    |
| P                         | 1.75  |

### Technical Drawing

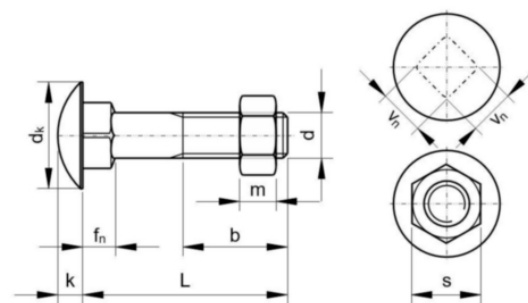

fn (max.) 8.75

s 19

Vn (max.) 12.7