

DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M12X280

Article number	08250.120.280
Brand	-
UBB	950351610742
UNSPSC	31161612
EAN	8715492556127
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M12
Length	280 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

NF	≈E27-351/E25-402
ISO	≈8677/4034
BS	≈4933/3692
NEN	≈303/697
DIN	603/555

Technical Specification

b (min.): 125mmL≤200mm	36
b (min.): L200mm	49
b (min.): L≤125mm	30
d-D	M12
dk (max.)	30.65
k (max.)	6.95
L (mm)	280
m	10
P	1.75

Technical Drawing

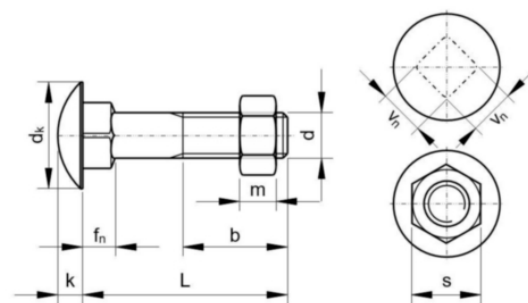

fn (max.) 8.75

s 19

Vn (max.) 12.7