

DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M16X60

Article number	08250.160.060
Brand	-
UBB	950351611401
UNSPSC	31161612
EAN	8715492556356
PKG. of 50	Full Box Only

Technical Parameters

Diameter	M16
Length	60 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

NEN	≈303/697
ISO	≈8677/4034
DIN	603/555
NF	≈E27-351/E25-402
BS	≈4933/3692

Technical Specification

b (min.): 125mmL≤200mm	44
b (min.): L200mm	57
b (min.): L≤125mm	38
d-D	M16
dk (max.)	38.8
k (max.)	8.95
L (mm)	60
m	13
P	2

Technical Drawing

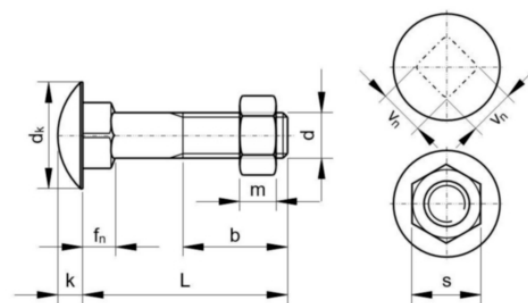

fn (max.) 12.9

s 24

Vn (max.) 16.7