

DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M16X110

Article number	08250.160.110
Brand	-
UBB	952351343845
UNSPSC	31161612
EAN	8715492556417
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M16
Length	110 mm
Class	4.6
Material	Steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Metric thread

Info

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


Standards

DIN	603/555
NF	≈E27-351/E25-402
ISO	≈8677/4034
NEN	≈303/697
BS	≈4933/3692

Technical Specification

b (min.): 125mmL≤200mm	44
b (min.): L200mm	57
b (min.): L≤125mm	38
d-D	M16
dk (max.)	38.8
k (max.)	8.95
L (mm)	110
m	13
P	2

Technical Drawing

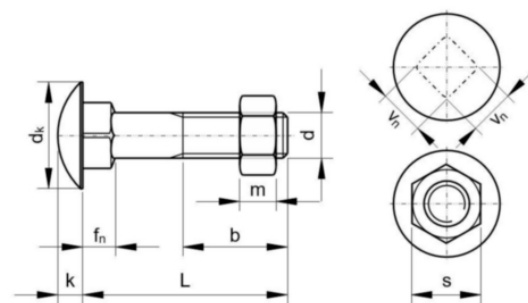

fn (max.) 12.9

s 24

Vn (max.) 16.7