

## DIN 603/555 Coach Bolt with Hexagon Nut, Zinc Plated, 4.6 M16X120

|                |               |
|----------------|---------------|
| Article number | 08250.160.120 |
| Brand          | -             |
| UBB            | 950351611815  |
| UNSPSC         | 31161612      |
| EAN            | 8715492556424 |
| PKG. of 25     | Full Box Only |

### Technical Parameters

|                   |               |
|-------------------|---------------|
| Diameter          | M16           |
| Length            | 120 mm        |
| Class             | 4.6           |
| Material          | Steel         |
| Thread direction  | Right         |
| Surface treatment | Zinc plated   |
| Thread            | Metric thread |

**Info**

The property class of the corresponding nuts is |4| as a minimum. Depending the supplier material class can differ (4.6 or 4.8)


### Standards

|     |                  |
|-----|------------------|
| BS  | ≈4933/3692       |
| NF  | ≈E27-351/E25-402 |
| DIN | 603/555          |
| NEN | ≈303/697         |
| ISO | ≈8677/4034       |

### Technical Specification

|                           |      |
|---------------------------|------|
| b (min.):<br>125mmL≤200mm | 44   |
| b (min.): L200mm          | 57   |
| b (min.): L≤125mm         | 38   |
| d-D                       | M16  |
| dk (max.)                 | 38.8 |
| k (max.)                  | 8.95 |
| L (mm)                    | 120  |
| m                         | 13   |
| P                         | 2    |

### Technical Drawing

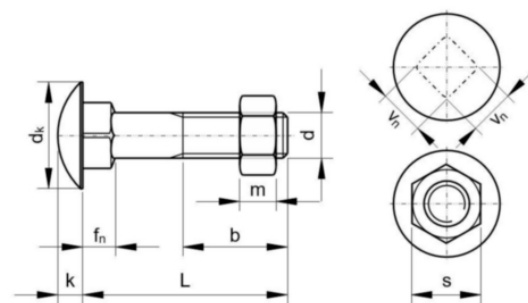

fn (max.) 12.9

s 24

Vn (max.) 16.7