


Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Steel ASTM A193 - ASTM A194 Plain Gr.B7M - Gr.2HM 1/2X55 (2.1/4)

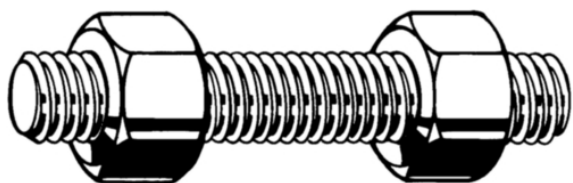

Article number	22085.127.057
Brand	-
UBB	500578756891
UNSPSC	31161619
EAN	8715494376617
PKG. of 1	Full Box Only

Technical Parameters

Diameter (inch)	1/2
Length (L) (mm)	55
Length (L) (Inch - ft)	2.1/4

Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Class	Gr.B7M - Gr.2HM
Material	Steel
Material technical	ASTM A193 - ASTM A194
Thread direction	Right
Surface treatment	Plain
Thread	Unified National Coarse

Standards

ASME	B16.5/B18.2.2
ASTM	A193/A194
BS	≈4882

Technical Specification

B	7/8
---	-----

Technical Drawing

M 12.3

Threads per inch 13

UP COURSE.

SETTING THE STANDARD
IN FASTENING SOLUTIONS

