


**Double end stud with
reduced shank with 2
hexagon nuts DIN 2510 L/
NF Steel 21CrMoV5-7+QT
(1.7709)/25CrMo4+QT
(1.7218) Plain M16X130**

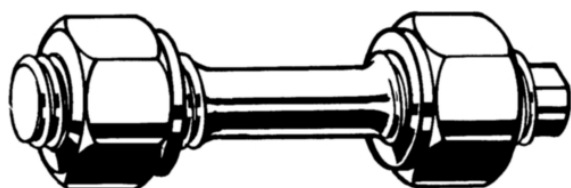

Article number	23530.160.130
Brand	-
UBB	500644895400
UNSPSC	31161619
EAN	8717077038943
PKG. of 1	Full Box Only

Technical Parameters

d ₁	M16
Length (L) (mm)	130
Info	External thread with large clearance according to DIN 2510-2.
Diameter (d-D)	M16
Marking	GA/KG
Material	Steel
Material technical	21CrMoV5-7+QT (1.7709)/25CrMo4+QT (1.7218)
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Standards

DIN	2510 L/NF
-----	-----------

Technical Specification

b	23
d ₂	12
m	16
P	2
s	27

Technical Drawing

