


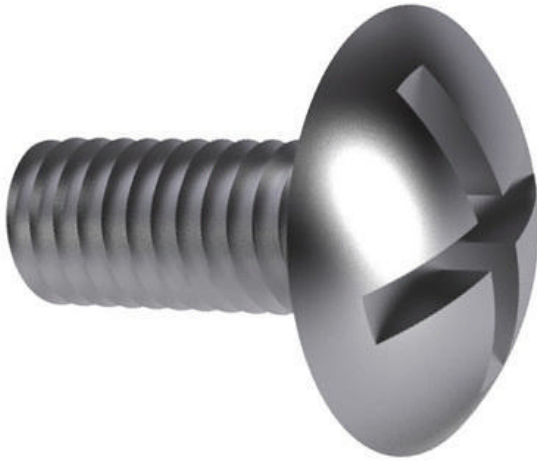

## Double slotted mushroom head screw NF E25-129 Steel Zinc plated 4.8 M4X25

|                |               |
|----------------|---------------|
| Article number | 24862.040.025 |
| Brand          | -             |
| UBB            | 950353760941  |
| UNSPSC         | 31161504      |
| EAN            | 8715493593596 |
| PKG. of 500    | Full Box Only |

### Technical Parameters

|                   |               |
|-------------------|---------------|
| Diameter          | M4            |
| Length            | 25 mm         |
| Class             | 4.8           |
| Driving features  | Slotted       |
| Head shape        | Button head   |
| Material          | Steel         |
| Surface treatment | Zinc plated   |
| Thread            | Metric thread |

### Standards

|    |         |
|----|---------|
| NF | E25-129 |
|----|---------|

### Technical Specification

|                         |     |
|-------------------------|-----|
| d-D                     | M4  |
| Thread length (min.)    | 38  |
| dk (max.)               | 10  |
| Full thread if $L \leq$ | 40  |
| k (max.)                | 2.2 |
| L (mm)                  | 25  |
| n                       | 1.2 |
| P                       | 0.7 |
| t (min.)                | 1   |

### Technical Drawing

