


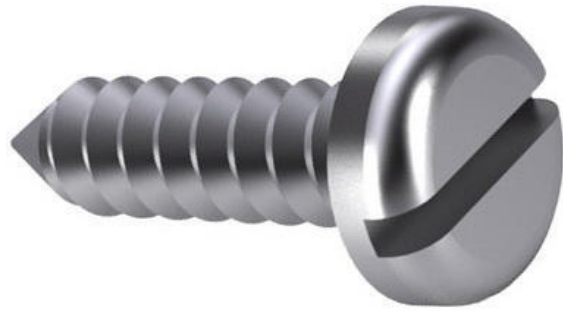

## Slotted pan head tapping screw DIN 7971 C Steel Nickel plated ST6,3X19MM

|                |               |
|----------------|---------------|
| Article number | 26000.063.019 |
| Brand          | -             |
| UBB            | 950352041897  |
| UNSPSC         | 31161507      |
| EAN            | 8715492650351 |
| PKG. of 100    | Full Box Only |

### Technical Parameters

|                   |                     |
|-------------------|---------------------|
| Diameter          | 6.3 mm              |
| Length            | 19 mm               |
| Driving features  | Slotted             |
| Head shape        | Pan head            |
| Material          | Steel               |
| Surface treatment | Nickel plated       |
| Thread            | Self tapping thread |

Info  
Warning:  
electroplating of  
these products may  
cause hydrogen  
embrittlement.

### Standards

|     |           |
|-----|-----------|
| ISO | 1481 C    |
| BS  | 4174      |
| NF  | E25-663 C |
| DIN | 7971 C    |

### Technical Specification

|        |      |
|--------|------|
| D (mm) | 6.3  |
| dk     | 12.5 |
| k      | 3.65 |
| L (mm) | 19   |
| n      | 1.6  |
| P      | 1.8  |

### Technical Drawing

