



Bearing preload disc spring Spring steel Phosphated 18,8X10,2X0,35MM

Article number	36460.198.003
Brand	-
UBB	950357386578
UNSPSC	31161811
EAN	8715492762993
PKG. of 50	Full Box Only

Technical Parameters


Diameter	10.2 mm
d _e	18.8
d _i	10.2
Material	Spring steel
Outer diameter	18.8
Surface treatment	Phosphated
Info	Warning: electroplating of these products may cause hydrogen embrittlement.F = spring load in Newton at a deflection s ≈ 0,75 h ₀ (h ₀ = l ₀ - t).Extensive technical data available on request.

Standards

Technical Specification

d _i (H12)	10.2
D (mm)	10.2
F	51
l ₀	0.7
t	0.71

Technical Drawing

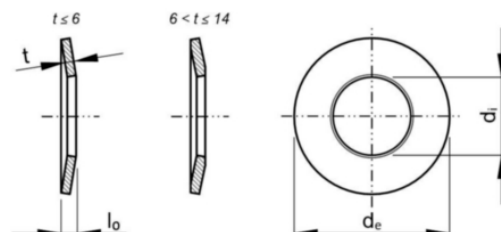

Thickness 0.35

FABORY