



Bearing preload disc spring Spring steel Phosphated 23,7X14,3X0,4MM

Article number	36460.251.004
Brand	-
UBB	950357386735
UNSPSC	31161811
EAN	8715492763013
PKG. of 50	Full Box Only

Technical Parameters


Diameter	14.3 mm
d _e	23.7
d _i	14.3
Material	Spring steel
Outer diameter	23.7
Surface treatment	Phosphated
Info	Warning: electroplating of these products may cause hydrogen embrittlement.F = spring load in Newton at a deflection s ≈ 0,75 h ₀ (h ₀ = l ₀ - t).Extensive technical data available on request.

Standards

Technical Specification

d _i (H12)	14.3
D (mm)	14.3
F	81
l ₀	0.9
t	0.89

Technical Drawing

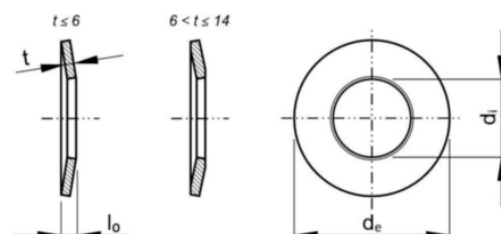

Thickness 0.4

FABORY