



Bearing preload disc spring Spring steel Phosphated 36,6X20,4X0,5MM

Article number	36460.386.005
Brand	-
UBB	950357490768
UNSPSC	31161811
EAN	8715492763075
PKG. of 25	Full Box Only

Technical Parameters


Diameter	20.4 mm
d _e	36.6
d _i	20.4
Material	Spring steel
Outer diameter	36.6
Surface treatment	Phosphated
Info	Warning: electroplating of these products may cause hydrogen embrittlement.F = spring load in Newton at a deflection s ≈ 0,75 h ₀ (h ₀ = l ₀ - t).Extensive technical data available on request.

Standards

Technical Specification

d _i (H12)	20.4
D (mm)	20.4
F	110
l ₀	1.3
t	1.3

Technical Drawing

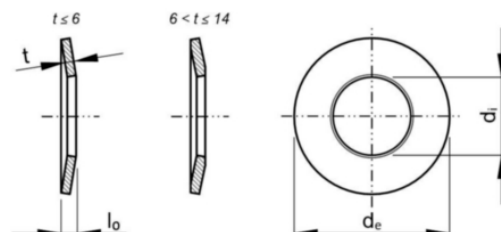

Thickness 0.5
FABORY