



Bearing preload disc spring Spring steel Phosphated 51,5X35,5X0,6MM

Article number	36460.550.006
Brand	-
UBB	950357490925
UNSPSC	31161811
EAN	8715492763112
PKG. of 10	Full Box Only

Technical Parameters


Diameter	35.5 mm
d _e	51.5
d _i	35.5
Material	Spring steel
Outer diameter	51.5
Surface treatment	Phosphated
Info	Warning: electroplating of these products may cause hydrogen embrittlement.F = spring load in Newton at a deflection s ≈ 0,75 h ₀ (h ₀ = l ₀ - t).Extensive technical data available on request.

Standards

Technical Specification

d _i (H12)	35.5
D (mm)	35.5
F	135
l ₀	1.5
t	1.5

Technical Drawing

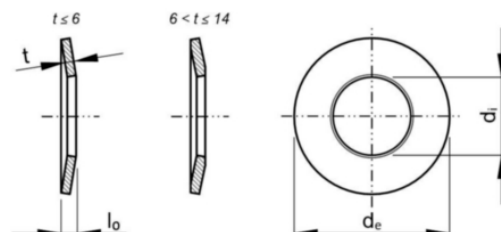

Thickness 0.6
FABORY