


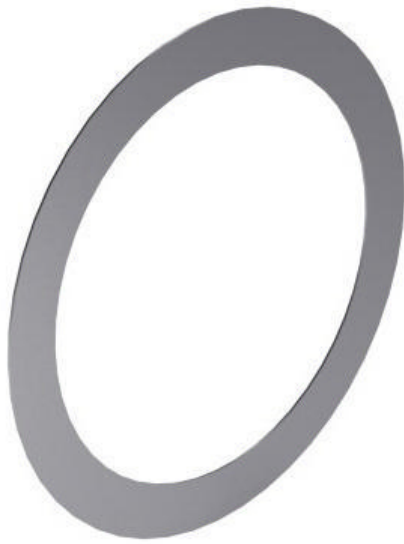

Shim ring thickness h=0,1mm DIN 988 Steel 2 K 50 Plain h=0,1mm 8X14MM

Article number	38600.080.014
Brand	-
UBB	950356607941
UNSPSC	31163301
EAN	8715492781192
PKG. of 100	Full Box Only

Technical Parameters

Diameter	8 mm
Material	Steel
Material technical	2 K 50
Outer diameter	14
Surface treatment	Plain
Info	h=0,1MM

Standards

DIN	988
-----	-----

Technical Specification

d1	8
d1 (max.)	8.19
d1 (min.)	8.04
d2	14
d2 (max.)	13.95
d2 (min.)	13.77
D (mm)	8
Thickness	0.1

Technical Drawing

