



Grooved pin, full length taper grooved DIN 1471 Free-cutting steel 1,5X16MM

Article number	39710.015.016
Brand	-
UBB	950359125008
UNSPSC	31163215
EAN	8715492823939
PKG. of 250	Full Box Only

Technical Parameters

Diameter	1.5 mm
Length	16 mm
Material	Free-cutting steel
Info	V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

ISO	≈8744
NEN	≈2602
DIN	1471

Technical Specification

c ≈	0.2
d1	1.5
d2 ≈	1.6
D (mm)	1.5
L (mm)	16

Technical Drawing

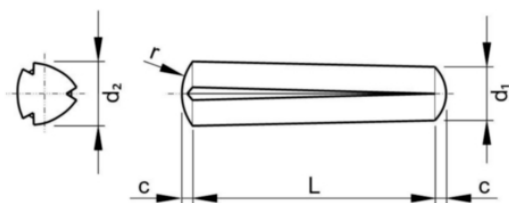

$r \approx$ 1.5

Tolerance h9

v 1.6